


VISHAY Rectifiers

RoHS Compliant This product is RoHS compliant.

Diodes & Rectifiers

Vishay General Semiconductor

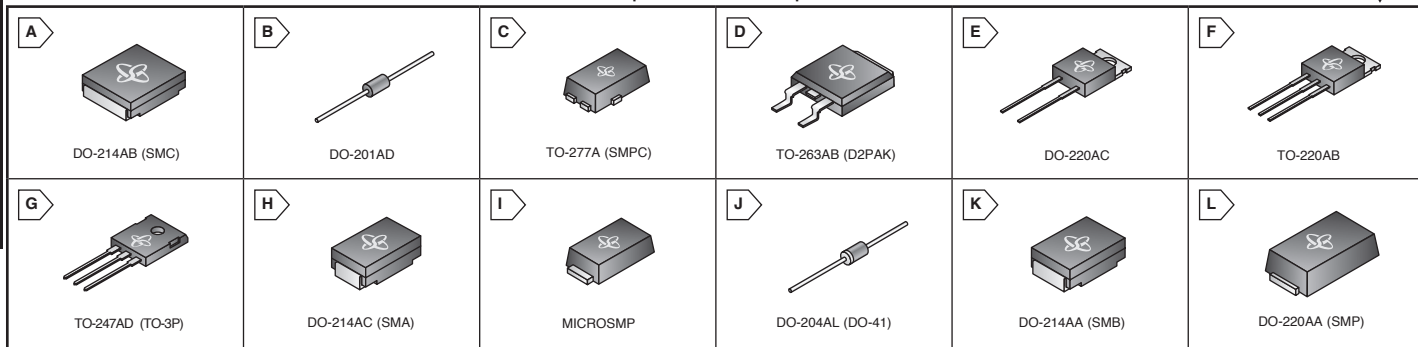

VISHAY ULTRA FAST (CONT.)



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Fig.	I _F (AV)	PRV (V)	IFM Surge (A)	Price Each			
						1	100	500	1000
625-ES3A-E3	ES3A-E3/57T	A	3A	50	100				
625-UF5400-E3	UF5400-E3/54	B	3A	50	150				
625-ES3B-E3	ES3B-E3/57T	A	3A	100	100				
625-UF5401-E3	UF5401-E3/54	B	3A	100	150				
625-ES3C-E3	ES3C-E3/57T	A	3A	150	100				
625-ES3D-E3	ES3D-E3/57T	A	3A	200	100				
625-MURS320-E3	MURS320-E3/57T	A	3A	200	125				
625-UF5402-E3	UF5402-E3/54	B	3A	200	150				
625-ES3F-E3	ES3F-E3/57T	A	3A	300	100				
625-UF5403-E3	UF5403-E3/54	B	3A	300	150				
625-ES3G-E3	ES3G-E3/57T	A	3A	400	100				
625-MURS340-E3	MURS340-E3/57T	A	3A	400	125				
625-UF5404-E3	UF5404-E3/54	B	3A	400	150				
625-UF5405-E3	UF5405-E3/54	B	3A	500	150				
625-AR3PJ-M3/86A	AR3PJ-M3/86A	C	3A	600	50				
625-MURS360-E3	MURS360-E3/57T	A	3A	600	125				
625-UF5406-E3	UF5406-E3/54	B	3A	600	150				
625-AU3PK-M3/86A	AU3PK-M3/86A	C	3A	800	45				
625-UF5407-E3	UF5407-E3/54	B	3A	800	150				
625-AU3PM-M3/86A	AU3PM-M3/86A	C	3A	1000	45				
625-AR3PM-M3/86A	AR3PM-M3/86A	C	3A	1000	50				
625-AS3PM-M3/86A	AS3PM-M3/86A	C	3A	1000	70				
625-UF5408-E3	UF5408-E3/54	B	3A	1000	150				
625-AS4PD-M3/86A	AS4PD-M3/86A	C	4A	200	100				
625-AS4PG-M3/86A	AS4PG-M3/86A	C	4A	400	100				
625-AR4PJ-M3/86A	AR4PJ-M3/86A	C	4A	600	65				
625-AS4PJ-M3/86A	AS4PJ-M3/86A	C	4A	600	100				
625-AS4PK-M3/86A	AS4PK-M3/86A	C	4A	800	100				
625-AR4PM-M3/86A	AR4PM-M3/86A	C	4A	1000	65				
625-AS4PM-M3/86A	AS4PM-M3/86A	C	4A	1000	100				
625-FES8BT-E3	FES8BT-E3/45	D	8A	100	125				
625-FES8DT-E3	FES8DT-E3/45	D	8A	200	125				
625-UHB10FT-E3	UHB10FT-E3/4W	E	10A	300	180				
625-UH10FT-E3	UH10FT-E3/4W	D	10A	300	180				
625-FEPB16DT-E3	FEPB16DT-E3/81	E	16A	200	200				
625-FESB16DT-E3	FESB16DT-E3/45	E	16A	200	250				
625-FEPB16GT-E3	FEPB16GT-E3/81	E	16A	400	125				
625-FEPB16JT-E3	FEPB16JT-E3/81	E	16A	600	125				
625-FESB16JT-E3	FESB16JT-E3/45	E	16A	600	250				
625-FEP16AT-E3	FEP16AT-E3/45	F	16A	50	200				
625-FES16AT-E3	FES16AT-E3/45	D	16A	50	200				
625-FEP16BT-E3	FEP16BT-E3/45	F	16A	100	200				
625-FES16BT-E3	FES16BT-E3/45	D	16A	100	200				
625-FEP16DT-E3	FEP16DT-E3/45	F	16A	200	200				
625-FES16DT-E3	FES16DT-E3/45	D	16A	200	200				
625-FES16FT-E3	FES16FT-E3/45	D	16A	300	200				
625-FEP16GT-E3	FEP16GT-E3/45	F	16A	400	200				
625-FES16GT-E3	FES16GT-E3/45	D	16A	400	200				
625-FEP16JT-E3	FEP16JT-E3/45	F	16A	600	200				

© Copyright 2015 Mouser Electronics

VISHAY ULTRA FAST (CONT.)



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Fig.	I _F (AV)	PRV (V)	IFM Surge (A)	Price Each			
						1	100	500	1000
625-FES16JT-E3	FES16JT-E3/45	D	16A	600	200				
625-FEP30AP-E3	FEP30AP-E3/45	G	30A	50	300				
625-FEP30BP-E3	FEP30BP-E3/45	G	30A	100	300				
625-FEP30DP-E3	FEP30DP-E3/45	G	30A	200	300				
625-FEP30GP-E3	FEP30GP-E3/45	G	30A	400	300				
625-FEP30BP-E3	FEP30BP-E3/45	G	30A	100	300				
625-FEP30GP-E3	FEP30GP-E3/45	G	30A	400	300				

VISHAY SCHOTTKY BARRIER



For quantities greater than listed, call for quote.

MOUSER STOCK NO.	Vishay Part No.	Fig.	I _F (AV)	PRV (V)	IFM Surge (A)	Price Each			
						1	100	500	1000
625-SS12-E3	SS12-E3/61T	F	1A	20	30				
625-MSS1P2L-M3	MSS1P2L-M3/89A	I	1A	20	25				
625-SS13-E3	SS13-E3/61T	H	1A	30	30				
625-SS14-E3	SS14-E3/61T	H	1A	40	30				
625-MSS1P4-M3	MSS1P4-M3/89A	I	1A	40	25				
625-SS15-E3	SS15-E3/61T	H	1A	50	30				
625-SS16-E3	SS16-E3/61T	H	1A	60	30				
625-MSS1P6-M3	MSS1P6-M3/89A	I	1A	60	25				
625-SS1H10-E3	SS1H10-E3/61T	H	1A	100	50				
625-1N5817-E3	1N5817-E3/54	J	1A	20	25				
625-1N5818-E3	1N5818-E3/54	J	1A	30	25				
625-1N5819-E3	1N5819-E3/54	J	1A	40	25				
625-SB160-E3	SB160-E3/54	J	1A	60	50				
625-SL12-E3	SL12-E3/61T	H	1.5A	20	50				
625-SL13-E3	SL13-E3/61T	H	1.5A	30	50				
625-SS22-E3	SS22-E3/52T	K	2A	20	50				
625-SL22-E3	SL22-E3/52T	K	2A	20	100				
625-SS23-E3	SS23-E3/52T	K	2A	30	50				
625-SSA23L-E3	SSA23L-E3/61T	H	2A	30	60				
625-SL23-E3	SL23-E3/52T	K	2A	30	100				
625-SS24-E3	SS24-E3/52T	K	2A	40	50				
625-SS2P4-M3/84A	SS2P4-M3/84A	L	2A	40	50				
625-SSA24-E3	SSA24-E3/61T	H	2A	40	60				
625-SS25-E3	SS25-E3/52T	K	2A	50	50				
625-SS26-E3	SS26-E3/52T	K	2A	60	50				
625-SS2H10-E3	SS2H10-E3/52T	K	2A	100	75				
625-SS32-E3	SS32-E3/57T	A	3A	20	100				
625-SSA33L-E3	SSA33L-E3/61T	H	3A	30	75				
625-SS33-E3	SS33-E3/57T	A	3A	30	100				
625-SS3P4L-M3	SS3P4L-M3/86A	C	3A	40	150				
625-SSA34-E3	SSA34-E3/61T	H	3A	40	75				
625-1N5820-E3	1N5820-E3/54	B	3A	20	80				
625-1N5821-E3	1N5821-E3/54	B	3A	30	80				
625-1N5822-E3	1N5822-E3/54	B	3A	40	80				

© Copyright 2015 Mouser Electronics